



서포트 부품, 조절형**품목 설명/제품 이미지****설명**

재질:
단강.

표면 마무리:
기본 몸체 검정 산화 처리장착 나사 경화 처리 및 검정 산화 처리

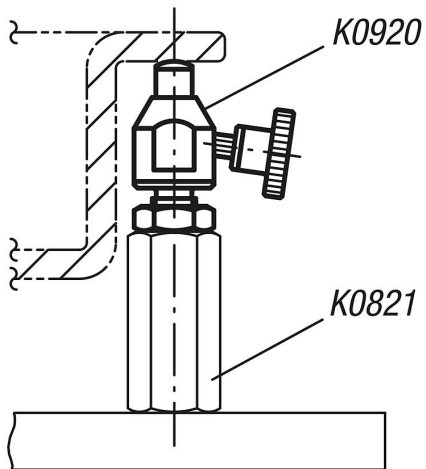

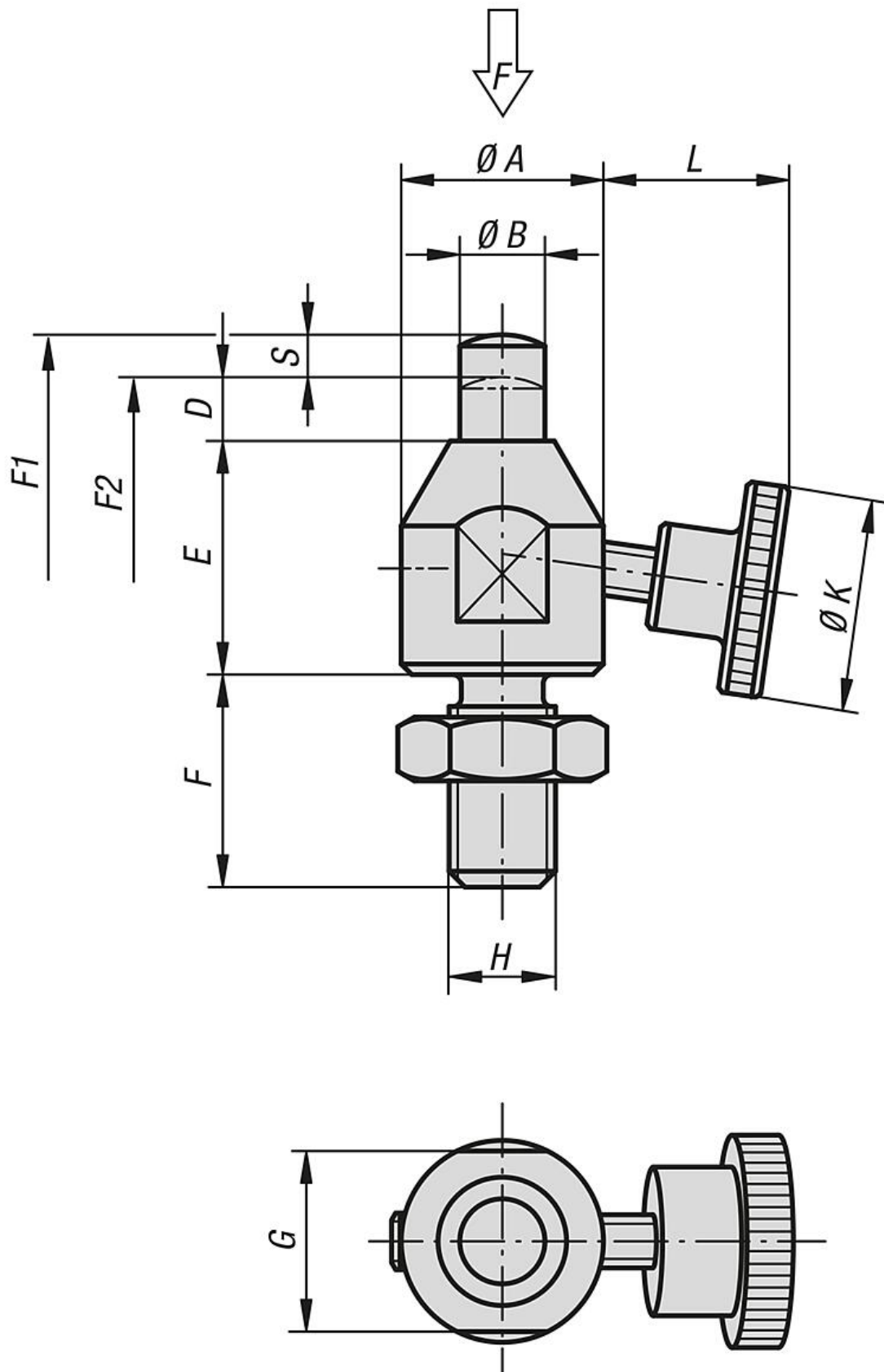



품목 요약

서포트 부품, 조절형

주문 번호	A	B	D	E	F	G	H	K	L	F N	스트로크 S	시작 탄성 F1 약. N	탄성 종료 F2 약. N
K0920.08023	15	6	5	18	16	13	M8	20	13,2	200	3	1,5	3
K0920.10028	19	8	6	22	20	17	M10	25	16,3	300	4	1,8	3
K0920.12031	22	10	6	25	24	19	M12	28	22,3	400	4	1,8	3