



텐션 클램프 K0910.3240...

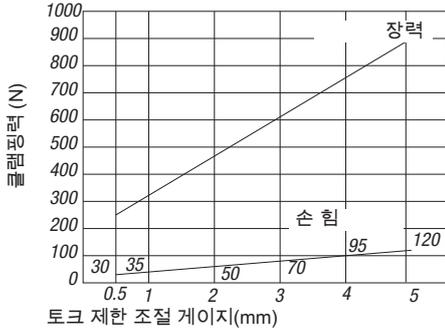


900N의 클램핑력에서 토크 제한 조절 게이지는 5mm이고 그림의 손 힘은 120N입니다.


텐션 클램프 K0910.4050...

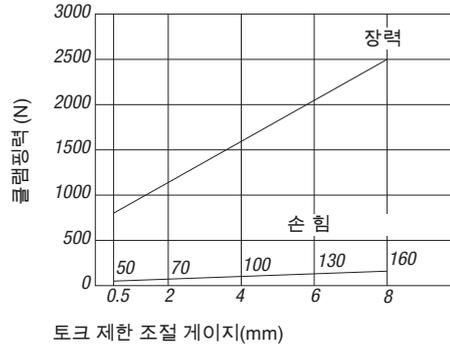


스윙 클램프 K0912....3232

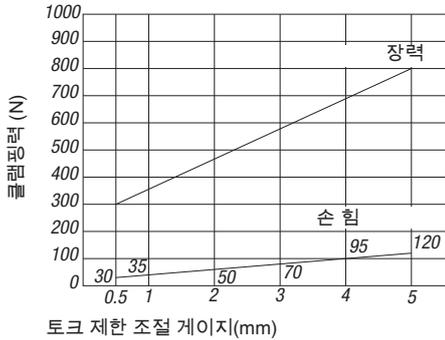


스윙 클램프 K0912....4540

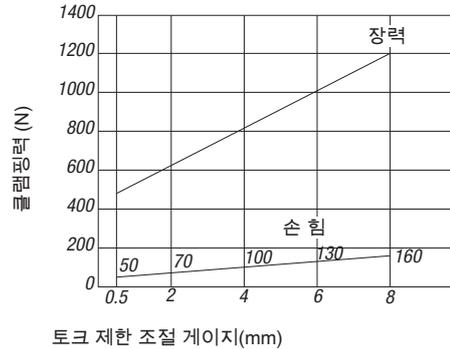

폴다운 스프링 반환 클램프 K0928.0500  
폴다운 스프링 반환 클램프 K0928.0501

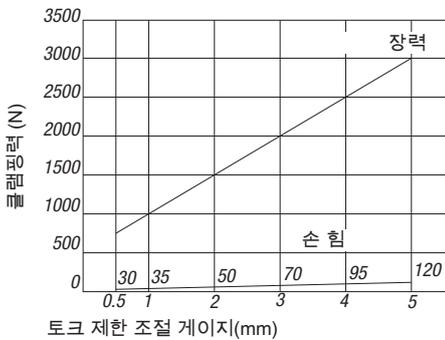

폴다운 스프링 반환 클램프 K0928.0800  
폴다운 스프링 반환 클램프 K0928.0801

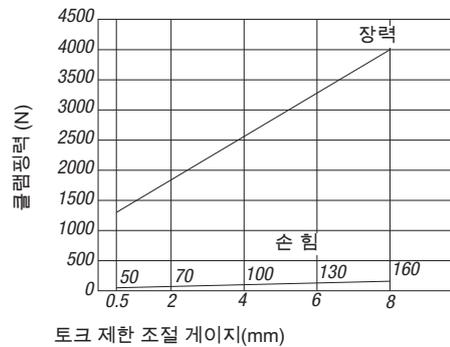

주의:  
상기 성능 곡선은 그리스가 제거된 클램프에 적용됩니다.