


조립 설명서 K2087

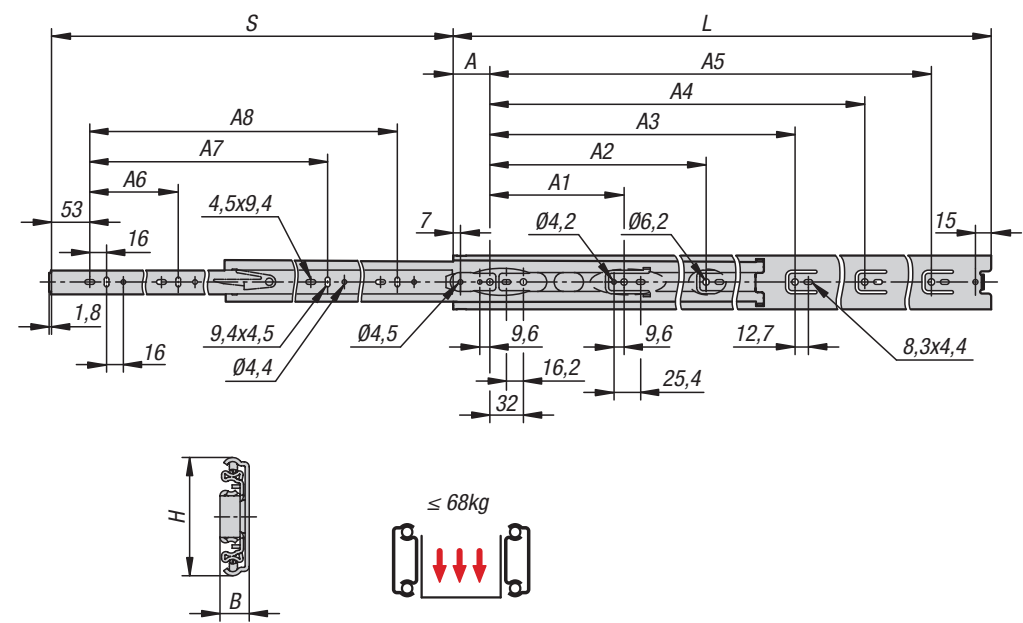

주문 번호	L	S	A1	A2	A3	A4	A5	A6	A7	A8	하중 쌍 당 kg
K2087.0250	250	250	-	96	160	-	-	160	-	-	68
K2087.0300	300	300	96	224	-	-	-	192	-	-	68
K2087.0350	350	350	128	256	-	-	-	96	256	-	68
K2087.0400	400	400	128	192	320	-	-	128	288	-	68
K2087.0450	450	450	128	256	352	-	-	160	352	-	68
K2087.0500	500	500	128	224	288	416	-	192	384	-	68
K2087.0550	550	550	128	224	352	448	-	192	448	-	68
K2087.0600	600	600	128	224	352	512	-	224	480	-	68
K2087.0650	650	650	128	224	352	448	576	256	544	-	68
K2087.0700	700	700	128	224	352	480	608	256	448	576	68

최대 하중 값을 달성하려면 모든 장착 위치를 사용해야 합니다.

평평한 장착에 적합하지 않음.
서랍 부착 시 볼 케이지를 전면에 고정하십시오.

레일 고정

