


조립 설명서 K2090

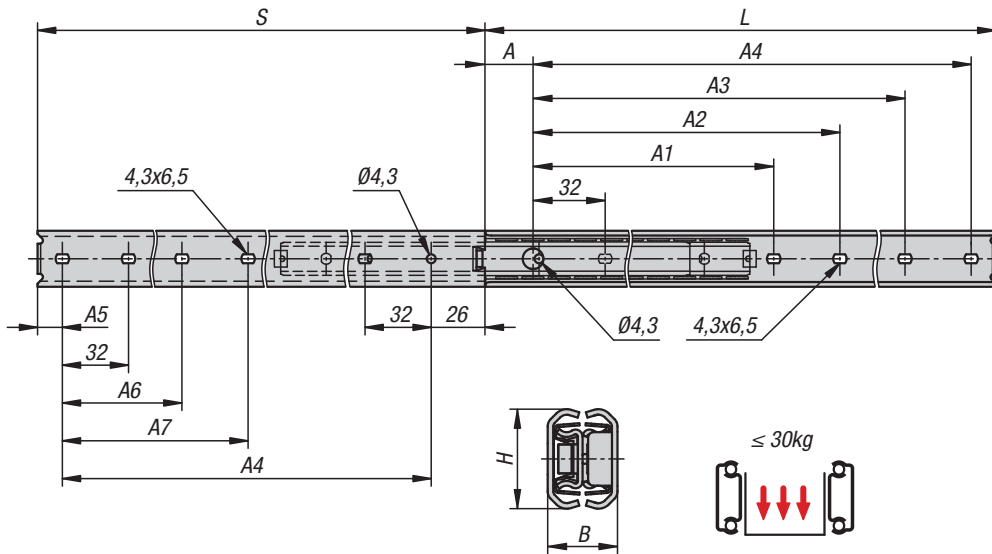

주문 번호	L	S	A	A1	A2	A3	A4	A5	A6	A7	B	H	하중 쌍 당 kg
K2090.0200	200	205,5	26	-	-	128	160	14	-	-	19	27,1	22
K2090.0250	250	255	26	-	-	160	192	32	-	-	19	27,1	25
K2090.0300	300	304	26	-	-	224	256	18	-	-	19	27,1	28
K2090.0350	350	353	26	-	-	256	288	36	-	-	19	27,1	30
K2090.0400	400	402	26	192	224	320	352	22	128	160	19	27,1	30
K2090.0450	450	452	26	224	256	384	416	8	160	192	19	27,1	28
K2090.0500	500	501	26	256	288	416	448	26	160	192	19	27,1	25
K2090.0550	550	550	26	256	288	480	512	12	224	256	19	27,1	22
K2090.0600	600	599	26	288	320	512	544	30	224	256	19	27,1	20

최대 하중 값을 달성하려면 모든 장착 위치를 사용해야 합니다.

서랍 중앙선이나 그 아래에 레일을 설치하십시오.

평평한 장착에 적합하지 않음.

레일 고정

