

설치 각도 기술 정보 K2093



클램핑 암 설치 및 분해:

모든 레일 길이를 커버하기 위해 네 가지 각도 길이를 개별적으로 또는 결합하여 사용할 수 있습니다. 필요한 앵글 키트 개수를 확인하려면 아래 표를 참조하세요. 동봉된 나사는 K1717 레일에 맞지 않으므로 M6 접시머리 나사를 권장합니다.



품목 번호	-305		-406		-559		-711	
	S	B	S	B	S	B	S	B
K1719.03050	1	2						
K1719.03051	1	2						
K1719.03560	1	2						
K1719.03561	1	2						
K1719.04060			1	2				
K1719.04061			1	2				
K1719.04570			1	2				
K1719.04571			1	2				
K1719.05080			1	2				
K1719.05081			1	2				
K1719.05590					1	2		
K1719.05591					1	2		
K1719.06100					1	2		
K1719.06101					1	2		
K1719.06600					1	2		
K1719.06601					1	2		
K1719.07110							1	2
K1719.07111							1	2
K1719.07620							1	2
K1719.07621							1	2
K1719.08130							1	2
K1719.08131							1	
K1719.08640	2	4						
K1719.08641	2	4						
K1719.09140	2	4						
K1719.09141	2	4						
K1719.10160	1	3			1	1		
K1719.10161	1	3			1	1		
K1719.10670	1	3					1	1
K1719.10671	1	3					1	1
K1719.12190	1	3					1	1
K1719.12191	1	3					1	1
K1719.13720		1		1	2	2		
K1719.13721		1		1	2	2		
K1719.15240					1	3	1	1
K1719.15241					1	3	1	1

품목 번호	-305		-406		-559		-711	
	S	B	S	B	S	B	S	B
K1720.0254								
K1720.0305	1	2						
K1720.0356	1	2						
K1720.0406			1	2				
K1720.0457			1	2				
K1720.0508			1	2				
K1720.0559					1	2		
K1720.0610					1	2		
K1720.0660					1	2		
K1720.0711							1	2
K1720.0762							1	2
K1720.0813							1	2
K1720.0864	2	4						
K1720.0914	2	4						
K1720.1016	1	2			1	2		
K1720.1067	1	2				1	1	1
K1720.1118	1	2			1	2		
K1720.1220	1	2					1	2
K1720.1372				1	2	3		
K1720.1524					1	2	1	2
K1717.0305	1	2						
K1717.0356	1	2						
K1717.0407			1	2				
K1717.0457			1	2				
K1717.0508			1	2				
K1717.0559					1	2		
K1717.0610					1	2		
K1717.0660					1	2		
K1717.0711							1	2
K1717.0762							1	2
K1717.0813							1	2
K1717.0864		2					1	1
K1717.0914	1	3	1	1				





S = 측면 장착

B = 하단 장착

측면 장착:

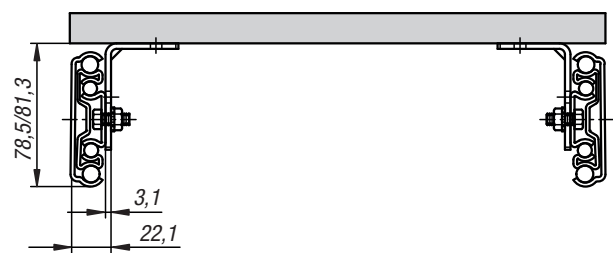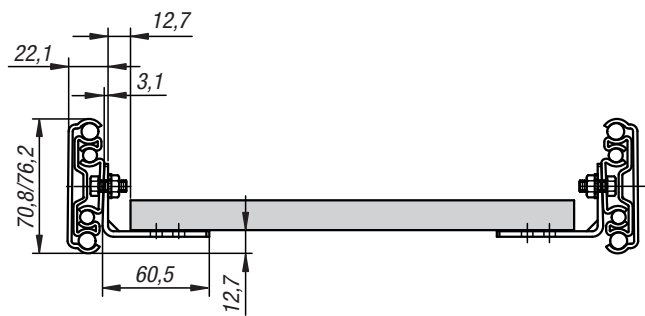

:

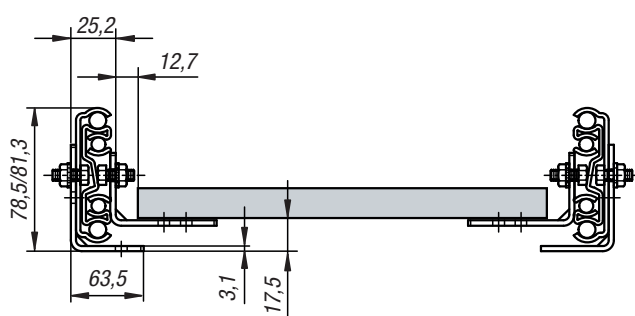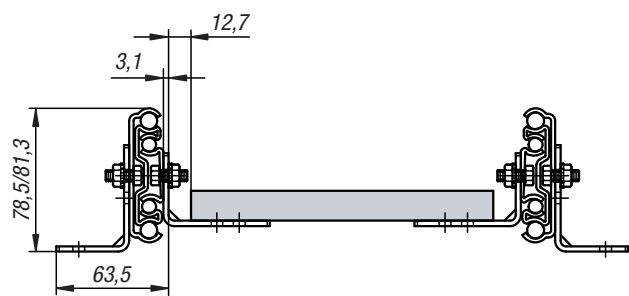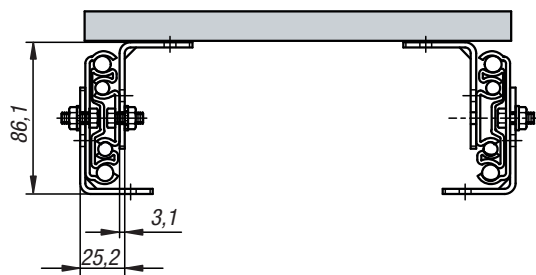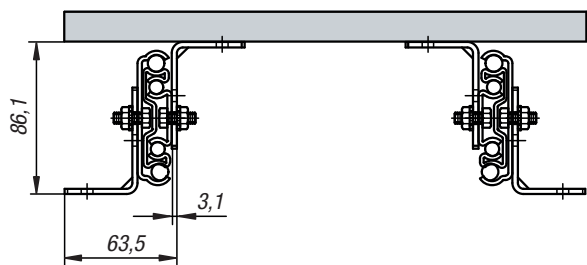





설치 각도 기술 정보 K2093



텔레스코픽 레일용 마운팅 브래킷 스틸

설치 각도	사진	IM/OM:	텔레스코픽 레일:
K2093.0305		IM	K1720.0305 K1719.03050 K1719.03051
K2093.0305		OM	K1720.0305 K1719.03050 K1719.03051
K2093.0305		IM	K1720.0356 K1719.03560 K1719.03561
K2093.0305		OM	K1720.0356 K1719.03560 K1719.03561
K2093.0406		IM	K1720.0406 K1719.04060 K1719.04061
K2093.0406		OM	K1720.0406 K1719.04060 K1719.04061
K2093.0406		IM	K1720.0457 K1719.04570 K1719.04571
K2093.0406		OM	K1720.0457 K1719.04570 K1719.04571
K2093.0406		IM	K1720.0508 K1719.05080 K1719.05081
K2093.0406		OM	K1720.0508 K1719.05080 K1719.05081
K2093.0559		IM	K1720.0559 K1719.05590 K1719.05591
K2093.0559		OM	K1720.0559 K1719.05590 K1719.05591
K2093.0559		IM	K1720.0610 K1719.06100 K1719.06101
K2093.0559		OM	K1720.0610 K1719.06100 K1719.06101
K2093.0559		IM	K1720.0660 K1719.06600 K1719.06601
K2093.0559		OM	K1720.0660 K1719.06600 K1719.06601
K2093.0711		IM	K1720.0711 K1719.07110 K1719.07111
K2093.0711		OM	K1720.0711 K1719.07110 K1719.07111
K2093.0711		IM	K1720.0762 K1719.07620 K1719.07621

    텔레스코픽 레일용 마운팅 브래킷 스틸

설치 각도	사진	IM/OM:	텔레스코픽 레일:
K2093.0711		OM	K1720.0762 K1719.07620 K1719.07621
K2093.0711		IM	K1720.0813 K1719.08130 K1719.08131
K2093.0711		OM	K1720.0813 K1719.08130 K1719.08131
2x K2093.0305		IM	K1720.0864
2x K2093.0305		IM	K1719.08640 K1719.08641
2x K2093.0305		OM	K1720.0864 K1719.08640 K1719.08641
2x K2093.0305		IM	K1720.0914 K1719.09140 K1719.09141
2x K2093.0305		OM	K1720.0914 K1719.09140 K1719.09141
1x K2093.0305 + 1x K2093.0559		IM	K1719.10160 K1719.10161 K1720.1016
1x K2093.0305 + 1x K2093.0559		OM	K1720.1016
2x K2093.0305		OM	K1719.10160 K1719.10161
1x K2093.0305 + 1x K2093.0711		IM	K1720.1067 K1719.10670 K1719.10671
1x K2093.0305 + 1x K2093.0559		OM	K1720.1067
2x K2093.0305		OM	K1719.10670 K1719.10671
1x K2093.0305 + 1x K2093.0559		IM	K1720.1118
1x K2093.0305 + 1x K2093.0559		OM	K1720.1118
1x K2093.0305 + 1x K2093.0711		IM	K1720.1220 K1719.12190 K1719.12191/
1x K2093.0305 + 1x K2093.0711		OM	K1720.1220
2x K2093.0305		OM	K1719.12190 K1719.12191

설치 각도 기술 정보 K2093



텔레스코픽 레일용 마운팅 브래킷 스틸

설치 각도	사진	IM/OM:	텔레스코픽 레일:
1x K2093.0559 + 1x K2093.0406		OM	K1720.1372
2x K2093.0559		IM	K1720.1372 K1719.13720 K1719.13721
1x K2093.0305 + 1x K2093.0406		OM	K1719.13720 K1719.13721
1x K2093.0559 + 1x K2093.0711		IM	K1720.1524 K1719.15240 K1719.15241
1x K2093.0559 + 1x K2093.0711		OM	K1720.1524
2x K2093.0559		OM	K1719.15240 K1719.15241

IM = 내부 레일
OM = 외부 레일